

Multi-Function C-Clamp



FEATURES

Multi-functional beam clamp

Use with Cable/Conduit/Pipe Clamp or Square Washer for Multi-Function C-Clamp

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Flange Thickness (FT)	Hole Size (HS)
C20HD	336100	1341213	Steel	Hot-Dip Galvanized	4 - 20 mm	14 mm
C20S4	336130	1319779	Stainless Steel 304 (EN 1.4301)		4 - 20 mm	14 mm
C45HD	336120	1341212	Steel	Hot-Dip Galvanized	30 - 44 mm	14 mm
C45S4	336150	1319781	Stainless Steel 304 (EN 1.4301)		30 - 44 mm	14 mm
C30S4	336140	1319780	Stainless Steel 304 (EN 1.4301)		17 - 30 mm	14 mm
C30HD	336110	1341214	Steel	Hot-Dip Galvanized	17 - 30 mm	14 mm


Table 2/2

Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Screw Length (L)	Torque (TQ)	Static Load
C20HD	336100	1341213	6	25mm	3 N·m	1100N
C20S4	336130	1319779	6	25mm	3 N·m	1100N
C45HD	336120	1341212	8	30mm	3 N·m	1100N
C45S4	336150	1319781	8	30mm	3 N·m	1100N
C30S4	336140	1319780	8	30mm	3 N·m	1100N
C30HD	336110	1341214	8	30mm	3 N·m	1100N

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

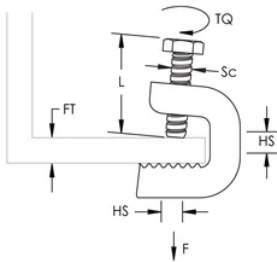

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

