

S Hook



FEATURES

For suspending chains, perforated bands, and similar items

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Diameter (Ø)	Length (L)
S30EG	591570	1341105	Steel	Electrogalvanized	3 mm	25mm
S40S4	591650	1319920	Stainless Steel 304 (EN 1.4301)		4 mm	35mm
S40EGSP25	172420		Steel	Electrogalvanized	4 mm	35mm
S40EG	591580	1341099	Steel	Electrogalvanized	4 mm	35mm
S50EG	591590	1319919	Steel	Electrogalvanized	5 mm	45mm
S50S4	591660		Stainless Steel 304 (EN 1.4301)		5 mm	45mm

Table 2/2

Catalog Number	Article Number	E-Number	Static Load
S30EG	591570	1341105	120N

Catalog Number	Article Number	E-Number	Static Load
S40S4	591650	1319920	250N
S40EGSP25	172420		250N
S40EG	591580	1341099	250N
S50EG	591590	1319919	400N
S50S4	591660		400N

DIAGRAMS

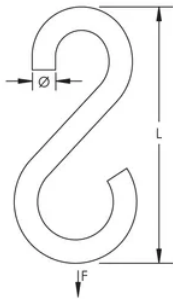

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

