


Rack Angle 19-inch and 23-inch Seismic, fits 2100x700mm, Black, Steel

Data Solutions

CATALOG NUMBER

ERA1921TPL

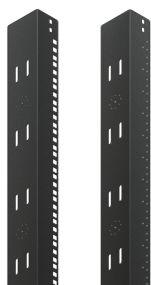

The 19-in. and 23-in. Rack Angles provide 19- or 23-in. rack spacing within a variety of Networking, Seismic, and PC cabinets. Rack Angles support any standard EIA spaced networking equipment designed to mount within a cabinet. The rack spacing, whether 19- or 23-in. is dependent on frame width. They are made of 14ga steel with square holes or 12 gauge steel with 10-32 tapped holes. Each SKU comes with a pair of rack angles.

FEATURES

The 19-in. and 23-in. Rack Angles provide 19- or 23-in. rack spacing within a variety of Networking, Seismic, and PC cabinets

Rack Angles support any standard EIA spaced networking equipment designed to mount within a cabinet

The rack spacing, whether 19- or 23-in. is dependent on frame width

They are made of 14 gauge steel with square holes or 12 gauge steel with 10-32 tapped holes

Each SKU comes with a pair of rack angles

PRODUCT ATTRIBUTES

Article Number: 11248

Material: Mild Steel

Finish: Powder Coated

Color: Jet Black

Color Code: RAL 9005

Thickness: 2.66mm

Hole Type: Tapped

Fits Frame Width: 700mm

Rack Units: 45U

Rack Width: 19in

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE