

nVent CADDY Cablecat J-Hook with BC200 Beam Clamp, Swivel, 3/4" dia, 1/8"–1/2" Flange

Data Solutions

CATALOG NUMBER

CAT12BC200B



CERTIFICATIONS



FEATURES

Beam clamp with attached nVent CADDY Cablecat J-Hook

Supports low voltage cables

Rotates 360 degrees to support various directional runs of cable

PRODUCT ATTRIBUTES


Material: Steel

Finish: Pregalvanized

Diameter (Ø): 0.75in

Flange Thickness (FT): 0.125 – 0.5in

DIAGRAMS

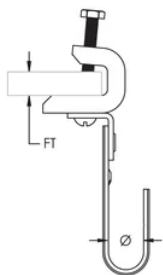

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE