

FleXbus Transformer Cover IP2X for 2 Conductors per Phase

Data Solutions

CATALOG NUMBER

FLEXCOVIP2XTWO



CERTIFICATIONS

**UK
CA**



CE

FEATURES

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

PRODUCT ATTRIBUTES

Article Number: 508161

Material: Polyvinylchloride

Working Temperature: -40 to 284°F


Length (L): 26.38in

Width (W): 9.05in

Depth (D): 7.09in

Unit Weight: 1.85lb

DIAGRAMS

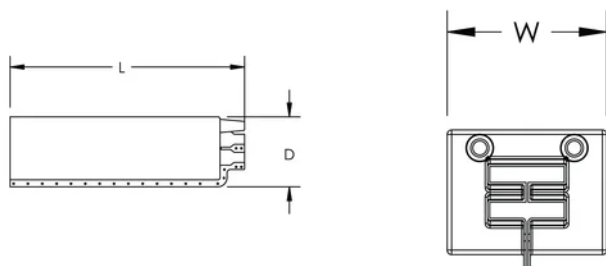

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE