

nVent ERICO System 3000 Interceptor

Data Solutions

CATALOG NUMBER

INTMKIVSS



FEATURES

Dynamic response to the approach of a lightning downleader

Designed for lower height installations

Non-radioactive technology

No external power required

PRODUCT ATTRIBUTES

Material: Stainless Steel 316 (EN 1.4401)

Temperature: -40 to 212°F

Installation Height (H): 65ft max

Diameter 1 (Ø1): 4in


Diameter 2 (Ø2): 1.03in

Height (H): 13.7in

Thread Size (TS): 1/2" BSPP

Unit Weight: 4.54lb

DIAGRAMS

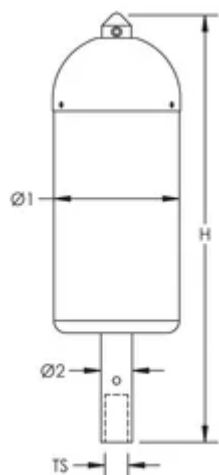

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE