


# Tool-less Shelf

## Data Solutions

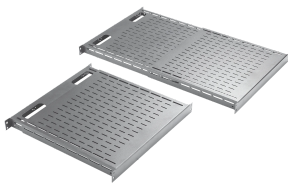

The Tool-less Shelf provides a support surface for equipment mounted within a 19in rack. It mounts onto rack angles that have EIA-spaced square holes (.375 inch). The shelf slides open and provides a variable-sized, continuous surface for equipment. The back of the shelf has oval cutouts for power and data cables. The shelf also features accessory hole patterns at the back of the shelf that fit small and large D-rings to help manage cable. It is rated for 150 lb. (68 kg) static load. NOTE: FOR SQUARE-HOLE RACK ANGLES ONLY!

### FEATURES

The Tool-less Shelf provides a support surface for equipment mounted within a 19in rack. It mounts onto rack angles that have EIA-spaced square holes (.375 inch)

The shelf slides open and provides a variable-sized, continuous surface for equipment

The back of the shelf has oval cutouts for power and data cables

The shelf also features accessory hole patterns at the back of the shelf that fit small and large D-rings to help manage cable

It is rated for 150 lb. (68 kg) static load

### SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material   | Finish        | Color      | Color Code | Thickness |
|----------------|----------------|------------|---------------|------------|------------|-----------|
| D19FVT912B     | 16691          | Mild Steel | Powder Coated | Jet Black  | RAL 9005   | 14ga      |
| D19FVT69B      | 16687          | Mild Steel | Powder Coated | Jet Black  | RAL 9005   | 14ga      |
| D19FVT912G     | 16692          | Mild Steel | Powder Coated | Light Gray | RAL 7035   | 14ga      |
| D19FVT69G      | 16688          | Mild Steel | Powder Coated | Light Gray | RAL 7035   | 14ga      |

Table 2/2

| Catalog Number | Article Number | Depth         | Hole Type |
|----------------|----------------|---------------|-----------|
| D19FVT912B     | 16691          | 31.2 – 45.3in | Square    |

| Catalog Number | Article Number | Depth         | Hole Type |
|----------------|----------------|---------------|-----------|
| D19FVT69B      | 16687          | 19.5 – 33.5in | Square    |
| D19FVT912G     | 16692          | 31.2 – 45.3in | Square    |
| D19FVT69G      | 16688          | 19.5 – 33.5in | Square    |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE