

# 19" Front Panel, Vented

Vented front panels allows heat dissipation through holes.



## CERTIFICATIONS



## FEATURES

Vented front panels (Aluminum ) allows heat dissipation

## SPECIFICATIONS

- Rack Width:** 95HP
- Material:** Aluminum
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/2

Catalog Number	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30118-962	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-047	1U	Anodized	Screw-on Front	1	Anodized	Anodized
30702-056	1U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-044	1U	Anodized	Screw-on Front	1	Raw	Conductive
30118-963	2U	Anodized	Screw-on Front	1	Painted	Painted
30702-048	2U	Anodized	Screw-on Front	1	Anodized	Anodized

Catalog Number	Rack Height	Finish	Mounting	Package Quantity	Front Finish	Rear Finish
30702-057	2U	Powder Coated	Screw-on Front	1	Painted	Painted
30118-964	3U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-058	3U	Powder Coated	Screw-on Front	1	Painted	Painted
30702-046	3U	Anodized	Screw-on Front	1	Raw	Raw
30702-045	2U	Anodized	Screw-on Front	1	Raw	Raw
30702-049	3U	Anodized	Screw-on Front	1	Anodized	Anodized


Table 2/2

Catalog Number	Treated Edges	Color Code	EMC Shielding	Type
30118-962		RAL 7021	No	19" Front Panel
30702-047	Yes		No	19" Front Panel
30702-056		RAL 7035	No	19" Front Panel
30702-044			No	19" Front Panel
30118-963		RAL 7021	No	19" Front Panel
30702-048	Yes		No	19" Front Panel
30702-057		RAL 7035	No	19" Front Panel
30118-964		RAL 7021	No	19" Front Panel
30702-058		RAL 7035	No	19" Front Panel
30702-046			No	19" Front Panel
30702-045			No	19" Front Panel
30702-049	Yes		No	19" Front Panel

## ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

## DIAGRAMS

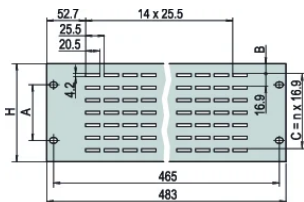

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**