

nVent CADDY Cat CM Double J-Hook, 70 Cable Capacity, Cat 5e, 30 Cable Capacity, Cat 6A

Data Solutions

NÚMERO DE CATÁLOGO

CAT100CM



CERTIFICATIONS



CARACTERÍSTICAS

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

System offers a convenient pathway for wires and cables

Double J-Hooks can be mounted vertically along the same drop rod to create a tree configuration

Allows addition of cables even when fixed flush to overhead decking

Specially designed double J-Hook has large-diameter, rounded support surfaces

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

CARACTERÍSTICAS DO PRODUTO

Número do artigo: 181976

Material: Aço

Acabamento: Electrogalvanized

Cable Capacity, Cat 5e: 70

Cable Capacity, Cat 6: 50

Cable Capacity, Cat 6A: 30

A: 185mm


Area: 80.2mm²

Tamanho do orifício (HS): 9.5mm

DETALHES ADICIONAIS DO PRODUTO

Area shown is the combined value for both sides. Divide by 2 for area of each side.

DIAGRAMAS

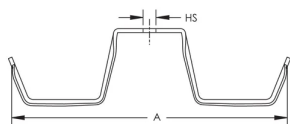

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE