

nVent CADDY Cat HP J-Hook Angle Bracket, 7.2 mm Hole

Data Solutions

NÚMERO DE CATÁLOGO

CATHPA4



CERTIFICATIONS



CARACTERÍSTICAS

Ideal for attaching to threaded rod, concrete, steel or wood surfaces

Requires no screws, rivets or special tools for assembly

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

CARATERÍSTICAS DO PRODUTO

Número do artigo: 181066


Material: Spring Steel

Acabamento: nVent CADDY Armour

Tamanho do orifício (HS): 7.2mm

Static Load: 667N

DIAGRAMAS

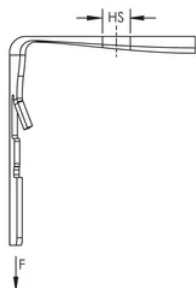

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE