


nVent CADDY Cat CM U-Hook

Data Solutions



CERTIFICATIONS

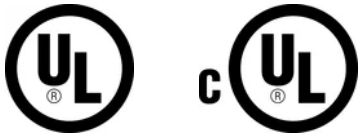

CARACTERÍSTICAS

Provides optimal support for high-performance data cable, up to and including Cat 5e, Cat 6, Cat 6A, Cat 7 and fibre optic

System offers a convenient pathway for wires and cables

Specially designed U-Hooks have large-diameter, rounded support surfaces

U-Hooks can be mounted vertically along the same drop rod to create a tree configuration

Cantilever mounting allows U-Hooks to be mounted to walls and columns with brackets

Rounded edges help prevent over-bending and kinking of cables

Ideal for retrofit applications where cable runs need to be routed around existing building infrastructure

Compliant with NEC® and ANSI®/TIA structured cabling systems standards

ESPECIFICAÇÕES

Acabamento: Electrolgalvanized

Material: Aço


Table 1/2

Número de catálogo	Cable Capacity, Cat 5e	Cable Capacity, Cat 6	Cable Capacity, Cat 6A	A	Area	Tamanho do orifício (HS)
CAT300CMLN	700	525	325	304mm	812mm ²	9.5mm
CAT200CMLN	450	350	215	203mm	533mm ²	9.5mm

Table 2/2

Número de catálogo	Static Load
CAT300CMLN	440N
CAT200CMLN	440N

DIAGRAMAS

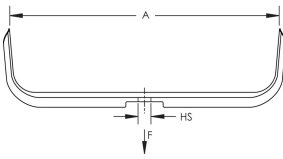

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.



O nosso forte portfólio de marcas:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE