
 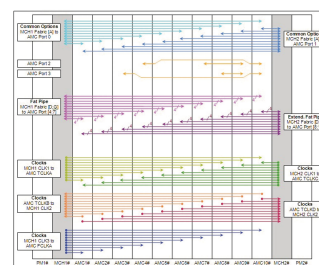


MTCA.0 System for 10 Single Full-Size AMC Modules, 3 U, 84 HP

NÚMERO DE CATÁLOGO

11850-011



The double AMC card cage on the right hand side can hold either 4 Double Full-size AMCs or, with the optional splitting kit, 8 Single Full-size AMCs.

CERTIFICATIONS



CARACTERÍSTICAS

In accordance with PICMG MTCA.0 R1.0 specification

3 U, 19" subrack system for 10 Single Full-Size AdvancedMC modules, 2 Single Full-Size MCHs and 2 power modules with width up to 12 HP

Instead of 8 Single Full-Size AdvancedMC modules, the right-hand board cage can be used for 4 Double Full-Size modules

Backplane with dual star topology, direct connections for S-ATA/SAS

Clock topology to PICMG AMC.0 R2.0

Two hot-swap fan modules in push/pull configuration, each with cooling unit manager (CU EMMC), airflow from right to left

Air filter is front accessible, with presence signal

CARACTERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 8

Tipo: 19" Rack Mount

Backplane Type: MTCA.0 Dual Star Topology

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 50W

Airflow Direction: Right to Left

Rack Height: 3U

Power Supply Type: (2) Single Full-size PM

Power Supply Included: Não

Rear I/O: Não

Em conformidade com: PICMG MTCA.0 R2.0

Profundidade: 216mm

Altura: 133.35mm

Net Weight: 7.9kg

Quantidade por embalagem: 1

DETALHES ADICIONAIS DO PRODUTO

Modified systems available on request.

Completely assembled, wired and tested.

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



O nosso forte portefólio de marcas:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE