


# CPCI System for Pluggable PSU, Horizontal, 3 U, 6 Slot

## NÚMERO DE CATÁLOGO

**24579-080**

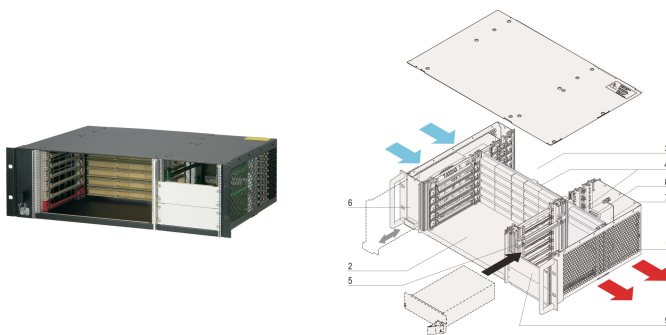

3 U CompactPCI System with horizontal Card Cage for six 6 U Boards, six RTM Boards and one CompactPCI 3 U Pluggable Power Supply. Option to assemble up to three pluggable Power Supplies.

## CERTIFICATIONS



## CARACTERÍSTICAS

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0

System with horizontal card cage. Board format Front: 6 U, 160 mm deep; Rear I/O: 6 U, 80 mm deep

Backplane (signal and power backplane in one unit) 6 slot, 6 U, 64 bit, System slot left, Power connector (2 x P 47)

Heat dissipation by hot-swap fan unit (airflow left to right)

Prepared for the assembly of a 19" CompactPCI power supply (3 U, 8 HP)

## CARATERÍSTICAS DO PRODUTO

Product Type: System

Number of Slots: 6

Tipo: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Tensão de entrada AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 3U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Não

Rear I/O: Sim

Em conformidade com: PICMG 2.0 R3.0

Profundidade: 275mm

Altura: 132.5mm

Largura: 449mm

Net Weight: 8.57kg

Quantidade por embalagem: 1

## DETALHES ADICIONAIS DO PRODUTO

---

Modified systems available on request.

48 VDC version on request.

## AVISO

---

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**