

# nVent CADDY Macrofix Insulated M8/M10, Stainless Steel, 108–118 mm OD, 4" Pipe, 100 DN

## NÚMERO DE CATÁLOGO

---

**MFD118S6**



## CERTIFICATIONS

---



## CARACTERÍSTICAS

---

Return-lip on the hanger prevents the rubber from detaching, eliminating rework during installation

Plastic washer prevents screws from falling out during installation

Combo head bolt works with slotted, hex, or Phillips drivers

Longer ears position the screw farther from the hanger, improving tool clearance when the screw is tightened

Combination nut can be attached to M8 or M10 threaded rod, simplifying material handling

Screw length has been optimized to accommodate an increased pipe range, reducing inventory

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

## CARACTERÍSTICAS DO PRODUTO

Número do artigo: 586314

Material: EPDM-SBR Rubber;Stainless Steel 316L (EN 1.4404)

Acabamento: Electropolished

Cor: Black

Temperatura: -50 to 110 °C

Diâmetro externo (OD): 108 - 118 mm

Tamanho do tubo: 4"

NB/DN: 100

Tamanho da haste (RS): M8;M10

Largura (W): 23 mm

Espessura (T): 1.75 mm

Diâmetro do parafuso (Sc): 6


Comprimento do parafuso (L): 37mm

Static Load: 1700N

## DETALHES ADICIONAIS DO PRODUTO

Lining is EPDM rubber.

## DIAGRAMAS

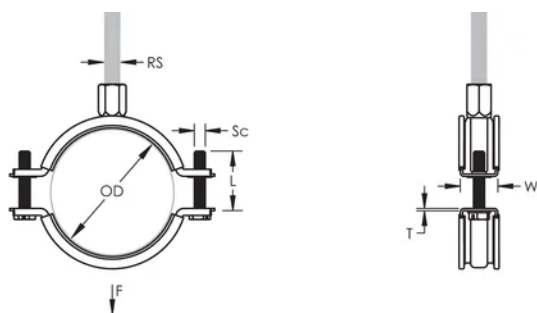

## AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### América do Norte

+1 800 753 9221

Opção 1 – Apoio ao cliente

Opção 2 – Assistência

técnica

### Europa

Países Baixos:

+31 800-0200135

França:

+33 800 901 793

### Europa

Alemanha:

800 1890272

Outros países:

+31 13 5835404

### APAC

Xangai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



O nosso forte portefólio de marcas:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

