


# Front Panel Kit, Shielded, Bottom Hinged, 4 U, 84 HP, 2.5 mm, Al, Front Anodized, Rear Conductive

## NÚMERO DE CATÁLOGO

**20848-607**

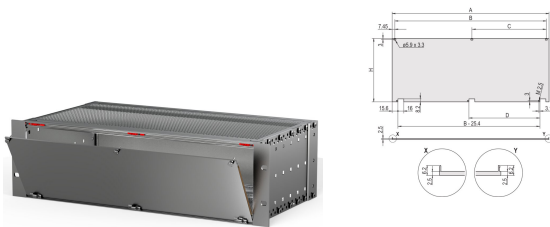

U-profile front panel bottom hinged for textile gasket.

## CERTIFICATIONS



## CARACTERÍSTICAS

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

## CARATERÍSTICAS DO PRODUTO

Rack Height: 4U

Accessory Type: Front panel

Rack Width: 84HP

Quantidade por embalagem: 1

Instalação: Hinged, Bottom

Gasket Type: Textile EMC

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Não

Em conformidade com: IEC 60297-3-101; IEEE 1101.1/10

Profundidade (D): 2.5mm

EMC Shielding: No (Retrofittable)

Acabamento: Anodized; Passivated

Altura (H): 172.9mm

Material: Alumínio

Product Type: Front Panel

Tipo: Front Panel without Handle

Largura (W): 426.4mm

Net Weight: 0.678kg


## DETALHES ADICIONAIS DO PRODUTO

---

Front panel can be removed in opened position ( $> 135^\circ$ ).

## DIAGRAMAS

---

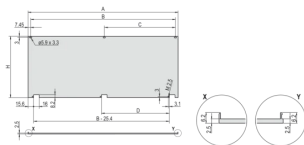

## AVISO

---

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em [www.nVent.com](http://www.nVent.com) e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



O nosso forte portefólio de marcas:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**