

# Heavy Duty Pipe Clamp per DIN 3567, Steel, HD, 26.9mm OD, 3/4" Pipe, 20 DN

## NUMĂR DE CATALOG

**DIN027HD**



## CARACTERISTICI

For high static requirements in industrial construction

Suitable for fix point applications

Can be welded onto T-beam to form a sliding element

## ATRIBUTE PRODUS

Article Number: 400199

Material: Oțel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 26.9 mm

Pipe Size: 3/4"

NB/DN: 20


Hole Size (HS): 11.5 mm

Width (W): 30 mm

Thickness (T): 5 mm

A: 64 mm

## DIAGRAMS

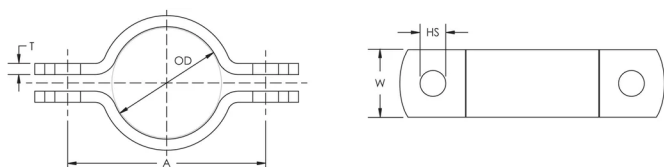

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

