

# OCDC Deck Hanger



## CARACTERISTICI

Provide a mobile mounting hole

Attaches to decking without having to drill or punch holes

Secured between the overlap of two steel sheets

## SPECIFICAȚII


Table 1/2

Număr de catalog	Article Number	Material	Finish	Hole Size (HS)	Flange Thickness (FT)	B
OCDC68MM	160700	Oțel	nVent CADDY Armour	6.8 mm	1.0 - 2.5 mm	54 mm

Table 2/2

Număr de catalog	Article Number	C	X	Static Load
OCDC68MM	160700	46 mm	13 x 8.5 mm	400N

## DIAGRAMS

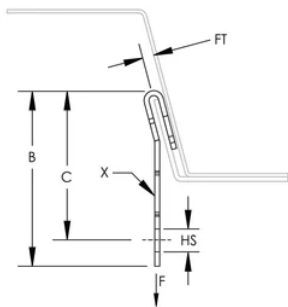

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

