

19" Front Panel

Data Solutions

Front panels made of Aluminum.



CERTIFICATIONS



CARACTERISTICI

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

SPECIFICAȚII

- Rack Width:** 95HP
- Material:** Aluminiu
- Accessory Type:** Front panel
- Product Type:** Front Panel

Table 1/3

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-299	1U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-948	1U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-098	1U	3mm	Screw-on Front	Anodized	Anodized	1

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
40304-074	1U	4mm	Screw-on Front	Anodized	Anodized	1
30219-137	7U	3mm	Screw-on Front	Anodized	Anodized	1
30118-956	9U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-113	6U	3mm	Screw-on Front	Anodized	Anodized	1
30219-110	5U	3mm	Screw-on Front	Vopsit Pulbere	Anodized	1
30219-107	4U	3mm	Screw-on Front	Anodized	Anodized	1
30118-949	2U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-950	3U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-104	3U	3mm	Screw-on Front	Anodized	Anodized	1
30118-951	4U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-303	4U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-101	2U	3mm	Screw-on Front	Anodized	Anodized	1
30118-952	5U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-302	3U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-953	6U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-954	7U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-957	10U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-955	8U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-301	2U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
40304-083	10U	4mm	Screw-on Front	Anodized	Anodized	1
40304-082	9U	4mm	Screw-on Front	Anodized	Anodized	1
40304-081	8U	4mm	Screw-on Front	Anodized	Anodized	1
40304-080	7U	4mm	Screw-on Front	Anodized	Anodized	1
40304-079	6U	4mm	Screw-on Front	Anodized	Anodized	1
40304-078	5U	4mm	Screw-on Front	Anodized	Anodized	1
40304-077	4U	4mm	Screw-on Front	Anodized	Anodized	1
40304-076	3U	4mm	Screw-on Front	Anodized	Anodized	1
30118-305	6U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
40304-075	2U	4mm	Screw-on Front	Anodized	Anodized	1
30118-306	7U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30118-307	8U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-144	10U	3mm	Screw-on Front	Anodized	Anodized	1
30118-304	5U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-143	9U	3mm	Screw-on Front	Anodized	Anodized	1

Număr de catalog	Rack Height	Depth (D)	Mounting	Finish	Front Finish	Package Quantity
30118-308	9U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1
30219-138	8U	3mm	Screw-on Front	Anodized	Anodized	1
30118-309	10U	3mm	Screw-on Front	Vopsit Pulbere	Painted	1

Table 2/3

Număr de catalog	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
30118-299	Painted		RAL 7035	No	43.6mm	19" Front Panel
30118-948	Painted		RAL 7021	No	43.6mm	19" Front Panel
30219-098	Anodized	No		No	43.6mm	19" Front Panel
40304-074	Anodized	Yes		No	43.6mm	19" Front Panel
30219-137	Anodized	No		No	310.3mm	19" Front Panel
30118-956	Painted		RAL 7021	No	399.2mm	19" Front Panel
30219-113	Anodized	No		No	265.9mm	19" Front Panel
30219-110	Anodized	No		No	221.4mm	19" Front Panel
30219-107	Anodized	No		No	177mm	19" Front Panel
30118-949	Painted		RAL 7021	No	88.1mm	19" Front Panel
30118-950	Painted		RAL 7021	No	132.5mm	19" Front Panel
30219-104	Anodized	No		No	132.5mm	19" Front Panel
30118-951	Painted		RAL 7021	No	177mm	19" Front Panel
30118-303	Painted		RAL 7035	No	177mm	19" Front Panel
30219-101	Anodized	No		No	88.1mm	19" Front Panel
30118-952	Painted		RAL 7021	No	221.4mm	19" Front Panel
30118-302	Painted		RAL 7035	No	132.5mm	19" Front Panel
30118-953	Painted		RAL 7021	No	265.9mm	19" Front Panel
30118-954	Painted		RAL 7021	No	310.3mm	19" Front Panel
30118-957	Painted		RAL 7021	No	443.7mm	19" Front Panel
30118-955	Painted		RAL 7021	No	354.8mm	19" Front Panel
30118-301	Painted		RAL 7035	No	88.1mm	19" Front Panel
40304-083	Anodized	Yes		No	443.7mm	19" Front Panel
40304-082	Anodized	Yes		No	399.2mm	19" Front Panel
40304-081	Anodized	Yes		No	354.8mm	19" Front Panel
40304-080	Anodized	Yes		No	310.3mm	19" Front Panel
40304-079	Anodized	Yes		No	265.9mm	19" Front Panel
40304-078	Anodized	Yes		No	221.4mm	19" Front Panel

Număr de catalog	Rear Finish	Treated Edges	Color Code	EMC Shielding	Height (H)	Type
40304-077	Anodized	Yes		No	177mm	19" Front Panel
40304-076	Anodized	Yes		No	132.5mm	19" Front Panel
30118-305	Painted		RAL 7035	No	265.9mm	19" Front Panel
40304-075	Anodized	Yes		No	88.1mm	19" Front Panel
30118-306	Painted		RAL 7035	No	310.3mm	19" Front Panel
30118-307	Painted		RAL 7035	No	354.8mm	19" Front Panel
30219-144	Anodized	No		No	443.7mm	19" Front Panel
30118-304	Painted		RAL 7035	No	221.4mm	19" Front Panel
30219-143	Anodized	No		No	399.2mm	19" Front Panel
30118-308	Painted		RAL 7035	No	399.2mm	19" Front Panel
30219-138	Anodized	No		No	354.8mm	19" Front Panel
30118-309	Painted		RAL 7035	No	443.7mm	19" Front Panel

Table 3/3


Număr de catalog	Width (W)
30118-299	483mm
30118-948	483mm
30219-098	483mm
40304-074	483mm
30219-137	483mm
30118-956	483mm
30219-113	483mm
30219-110	483mm
30219-107	483mm
30118-949	483mm
30118-950	483mm
30219-104	483mm
30118-951	483mm
30118-303	483mm
30219-101	483mm
30118-952	483mm
30118-302	483mm
30118-953	483mm
30118-954	483mm
30118-957	483mm

Număr de catalog	Width (W)
30118-955	483mm
30118-301	483mm
40304-083	483mm
40304-082	483mm
40304-081	483mm
40304-080	483mm
40304-079	483mm
40304-078	483mm
40304-077	483mm
40304-076	483mm
30118-305	483mm
40304-075	483mm
30118-306	483mm
30118-307	483mm
30219-144	483mm
30118-304	483mm
30219-143	483mm
30118-308	483mm
30219-138	483mm
30118-309	483mm

DETALII SUPLIMENTARE DESPRE PRODUS

Please order 19" assembly kit separately.

DIAGRAMS

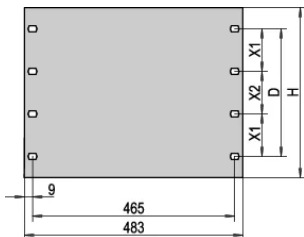

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și

avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE