

FleXbus Transformer Cover IP2X for 2 Conductors per Phase

Data Solutions

NUMĂR DE CATALOG

FLEXCOVIP2XTWO



CERTIFICATIONS

**UK
CA**



CE

CARACTERISTICI

Input/output for neutral/ground conductor

Resistance to solvent and hydrocarbon splashes

Installs quickly and easily

UV resistance

ATRIBUTE PRODUS

Article Number: 508161

Material: Polyvinylchloride

Working Temperature: -40 to 140°C


Length (L): 670mm

Width (W): 230mm

Depth (D): 180mm

Unit Weight: 0.84kg

DIAGRAMS

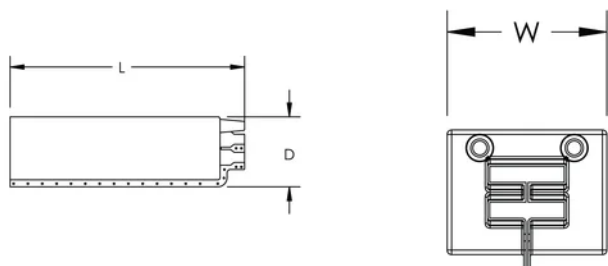

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE