

FleXbus HCBC Plate, 100 mm x 41 mm

Data Solutions

NUMĂR DE CATALOG

FLEXPLATE100



CERTIFICATIONS



CARACTERISTICI

Rigid tinned copper part provides strong electrical contact to maintain braid expansion during compression

HCBC Plate allows FleXbus Conductor insulation to overlap the connection palm

Tinned copper allows for copper or aluminum conductor connections

Installs quickly and easily

RoHS compliant

ATRIBUTE PRODUS

Article Number: 508181

Material: Copper

Finish: Tinned

A: 115mm

B: 63mm

C: 45mm

D: 51mm

Thickness (T): 5mm

Conductor Size: 960 mm²; 1280 mm²; 1810 mm²


Unit Weight: 0.32kg

DETALII SUPLIMENTARE DESPRE PRODUS

It is mandatory to use the HCBC Clamp associated with the HCBC Plate for proper Flexbus Conductor connection.

It is mandatory to use the PIN associated with the HCBC Plate for proper connection mechanical resistance.

DIAGRAMS

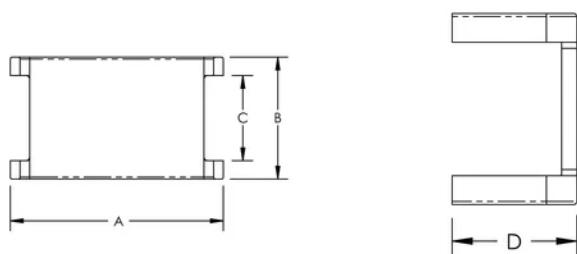

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE