


Four Pole Distrib. Block with Threaded Bars, 125 A

Data Solutions

NUMĂR DE CATALOG

TR-125A

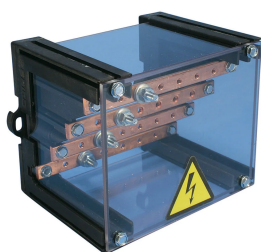

CERTIFICATIONS



CARACTERISTICI

Easily clips onto DIN rail or mounts to panel with screws

Equipped with a current input plug

Bolts included for output connections

Transparent protection cover

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

ATTRIBUTE PRODUS

Article Number: 563150

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (Ipk): 40kA

Short Term Withstand Current (Icw) 1s: 8.4kA

Line Side Number of Connections: 1

Load Side Number of Connections: 5

Thread Size 1 (TS1): M5

Thread Size 2 (TS2): M6

Depth (D): 117mm

Height (H): 126mm

Width (W): 150mm

Unit Weight: 0.68kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DETALII SUPLIMENTARE DESPRE PRODUS

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

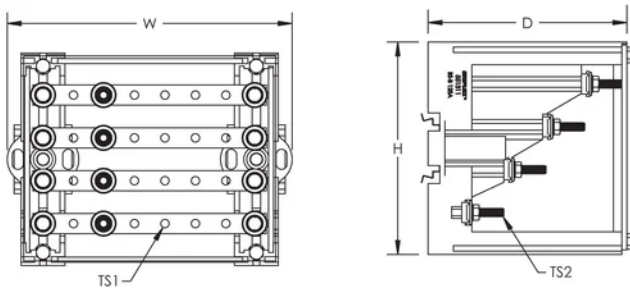

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE