

Four Pole Distrib. Block with Threaded Bars, Flat, 400 A

Data Solutions

NUMĂR DE CATALOG

TRC-400A



CERTIFICATIONS



CARACTERISTICI

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

ATTRIBUTE PRODUS

Article Number: 563180

Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 1000

Peak Short Circuit Current (I_{pk}): 118kA

Short Term Withstand Current (I_{cw}) 1s: 28kA

Line Side Number of Connections: 1

Load Side Number of Connections: 10

Thread Size 1 (TS1): M6

Thread Size 2 (TS2): M10

Depth (D): 50mm

Height (H): 338 – 390mm

Width (W): 260mm

A: 290mm

Unit Weight: 2.65kg

Flammability Rating: UL® 94V-0


Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DETALII SUPLIMENTARE DESPRE PRODUS

Thread Size 2 represents input plug.

Line side and load side number of connections are per pole.

DIAGRAMS

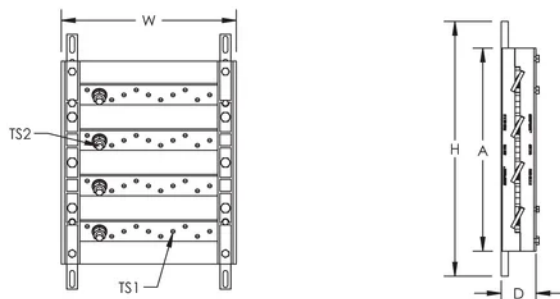

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răni corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE