


Four Pole Distrib. Block with Threaded Bars, 160 A

Data Solutions

NUMĂR DE CATALOG

TRS-160A

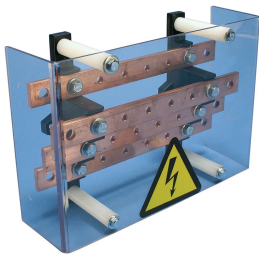

CERTIFICATIONS



CARACTERISTICI

- Easily fixes onto asymmetric DIN rail or mounts with screws
- Bolts included for output connections
- Transparent protection cover
- Easy accessibility for wiring
- Ready to use out of the box, saving installation time and labor
- RoHS compliant

ATTRIBUTE PRODUS

- Article Number: 563160
- Material: Copper; Glass Fibre Reinforced Polyamide; Plexiglass

Max Working Voltage, IEC (Ui): 630

Peak Short Circuit Current (Ipk): 34kA

Short Term Withstand Current (Icw) 1s: 13.2kA

Line Side Number of Connections: 2

Load Side Number of Connections: 4

Hole Size (HS): 8mm

Thread Size (TS): M6

Depth (D): 68mm

Height (H): 150mm

Width (W): 230mm

Unit Weight: 1.15kg


Flammability Rating: UL® 94V-0

Complies With: IEC® 60439.1; IEC® 61439.1; IEC® 60695-2-11 (Glow Wire Test 960 °C)

DETALII SUPLIMENTARE DESPRE PRODUS

Line side and load side number of connections are per pole.

DIAGRAMS

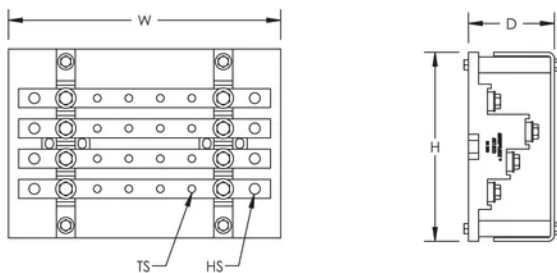

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE