


# Basic PDU, EB0850, 400 VAC, 3-PH, 32 A

## Data Solutions

### NUMĂR DE CATALOG

### EB0850

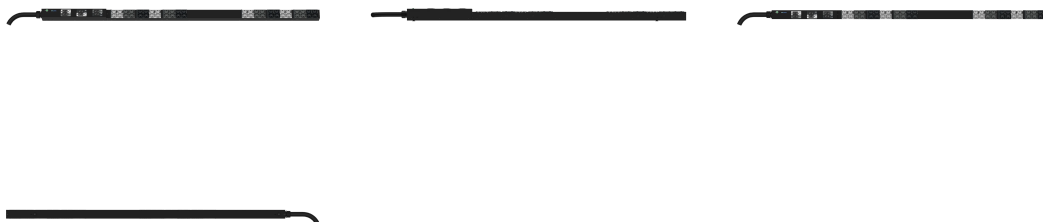

Modular, compact PDU. Ultra-Low Profile Design

### CARACTERISTICI

Enlogic Basic Power Distribution Units enable power in Cabinets as well as Open Frame Racks and Wall-Mount enclosures

Input Voltage 400 VAC, 3-phase

C13 and C19 outlets

1RU aluminum profile

Adjustable Toolless Mounting

### ATTRIBUTE PRODUS

Product Family: Enlogic

Type: Basic PDU

Product Type: Socket Strip

Socket Type: (24) C13/C15; (24) C13/C15/C19/C21

Socket Quantity: 48

Color: Black

Circuit Breaker: 16 A, 1-pole, Hy-Mag

Switched Outlets: No

Circuit Breaker Quantity: 6

Power Rating: 17.3 kVA North America; 22.1 kVA International

Input Cable Length: 1.8m

Input Cable Location: Top Feed

Input Voltage: 380 – 415V

Phase: 3 PH

Nominal Voltage: 415V

Max Power Input: 17.3 / 22.1 kVA

On/Off Switch Included: No

Amperage (Derated Amperage): 30 A (24 A) North America; 32 A International

Output Voltage: 208 – 230VAC

Rack Units: 0U

Plug Type: IEC 60309 530P6/532P6

Metering Type: None

Removable Input Cable: No

Material: Oțel

Finish: Vopsit Pulbere

Height: 1780mm

Width: 56mm

Depth: 55mm

Weight: 10kg

Package Quantity: 1

## DETALII SUPLIMENTARE DESPRE PRODUS

Please order bracket for vertical mounting separately.

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.



Portofoliul nostru puternic de mărci:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**