


# CompacPRO Front/Rear Panel, With Hidden Fixing

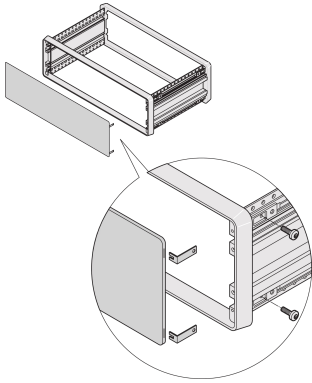

The front panel for CompacPRO Case mounts to the frame of the case. The front panel has no visible screws and can be used for front foil.

## CERTIFICATIONS



## CARACTERISTICI

Al panel, 2.5 mm

## SPECIFICAȚII

<b>Material:</b>	Aluminiu
<b>Finish:</b>	Anodized
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2

Număr de catalog	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized

Număr de catalog	Rack Height	Height	Rack Width	Width	Package Quantity	Front Finish
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-035	2U	84mm	42HP	238.7mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized

Table 2/2

Număr de catalog	Rear Finish	Treated Edges	Depth
24575-275	Anodized	No	2.5mm
24575-075	Anodized	No	2.5mm
24575-155	Anodized	No	2.5mm
24575-175	Anodized	No	2.5mm
24575-455	Anodized	No	2.5mm
24575-475	Anodized	No	2.5mm
24575-135	Anodized	No	2.5mm
24575-255	Anodized	No	2.5mm
24575-035	Anodized	No	2.5mm
24575-235	Anodized	No	2.5mm
24575-115	Anodized	No	2.5mm

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**