


Door Contact Switch Without Cable

NUMĂR DE CATALOG

20118-810

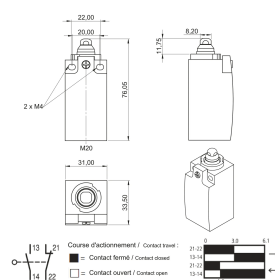

Door contact switch with magnetic contact, allows operational efficiency. This product is easy handlable by plug and play.

CERTIFICATIONS



CARACTERISTICI

Door contact switch (without connection cable)

ATTRIBUTE PRODUS

Product Type: Switch

Depth: 33.5mm

Height: 76.5mm

Operating Temperature: -25 to 75°C

Protection Rating: IP66

Width: 31mm

Complies With: UL® 508; EN 50047 form B

Current Rating: 3 – 6A

Gross Weight: 0.1kg

Package Quantity: 1

Voltage: 24 – 230V

Wire Size: 0.5 – 2.5mm²

DETALII SUPLIMENTARE DESPRE PRODUS

Please order bracket for installation of door switch (Varistar, Novastar, Eurorack) separately.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE