


CPCI Bridge, 32-Bit, 33 MHz

NUMĂR DE CATALOG

23006-920

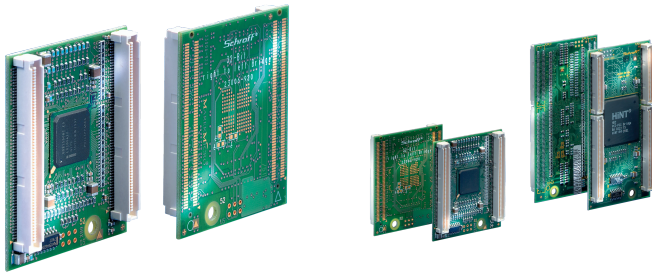

Very compact and low bridge shape, no interference with rear transition boards

CERTIFICATIONS



CARACTERISTICI

Bridge is designed for primary backplanes with system slot right; bridge for system slot left available on request

33 MHz capable

Bridge mounted on rear of backplane, hence no loss of slots

In accordance with: PICMG 2.6 CompactPCI Bridging Specification, PCI 2.1 PCI Local Bus Specification, Rev. 2.1

ATRIBUTE PRODUS

Product Type: Backplane

Backplane Type: CompactPCI Bridge, 32-bit, 33 MHz

System Slot: Right

Net Weight: 0.028kg

Package Quantity: 1

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE