
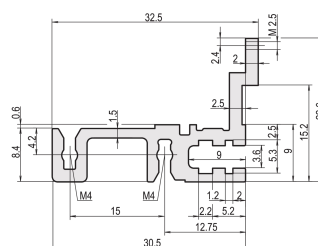


Horizontal Rail, Rear, Type H-MZ, Heavy, With Z-Rail, 20 HP

NUMĂR DE CATALOG

34560-920

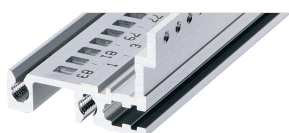

Combinations of horizontal rails and side panels

		Δ^2 = can be combined	Δ^1 = combination not recommended		
Page 1 # 1		-	+	+	not to repeat
Page 2 # 2		+	not to be used for assembly	+	not to be used for assembly
Page 3 # 3		not to be used	not to be used	+	not to be used
Page 4 # 4		+	+	-	-
Page 5 # 5		+	+	-	-
Page 6 # 6		+	+	-	-
Page 7 # 7		+	+	-	-
Page 8 # 8		+	+	-	-

The horizontal rail, type heavy with MZ enables the use of DIN connectors. The connectors are in accordance with EN 60603-2.

CERTIFICATIONS



CARATTERISTICI

For directly mounting connectors complying with EN 60603 (DIN 41612)

With Z-rail for high mechanical load (H-MZ)

Aluminum extrusion, anodized finish, conductive contact surface

ATTRIBUTE PRODUS

Rack Width: 20HP

Package Quantity: 1

Finish: Anodized

Length: 106.68mm

Material: Aluminu

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Horizontal Rail

Type: Heavy, MZ

Works With: Subracks; Cases

DETALII SUPLIMENTARE DESPRE PRODUS

Delivery is in standard pack multiples. Pricing is per individual item.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe www.nvent.com și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Portofoliul nostru puternic de mărci:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE