



# Front Panel 1 U, Horizontal Rail Mounting

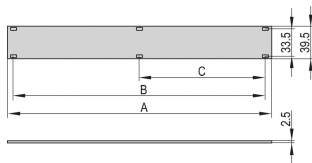

The 1 U front panel enables a user to cover the 1 U section in a 4 U PropacPRO case, RatiopacPRO 5 U (1-3-1) and EuropacPRO 4 U. The panel will be assembled to the threaded inserts of the horizontal rails.

## CERTIFICATIONS

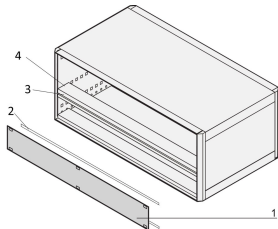

## CARACTERISTICI

Mounts on horizontal rails (upper, lower)

## SPECIFICAȚII

<b>Material:</b>	Aluminiu
<b>Finish:</b>	Anodized; Passivated
<b>Product Family:</b>	RatiopacPRO; PropacPRO; EuropacPRO
<b>Accessory Type:</b>	Front panel
<b>Product Type:</b>	Front Panel

Table 1/2


Număr de catalog	Rack Height	Height (H)	Rack Width	Width (W)	Depth (D)	Package Quantity
20850-423	1U	39.5mm	28HP	141.9mm	2.5mm	1
20850-425	1U	39.5mm	63HP	319.7mm	2.5mm	1

Număr de catalog	Rack Height	Height (H)	Rack Width	Width (W)	Depth (D)	Package Quantity
20850-426	1U	39.5mm	84HP	426.4mm	2.5mm	1
20850-424	1U	39.5mm	42HP	213mm	2.5mm	1

Table 2/2

Număr de catalog	Front Finish	Rear Finish	Treated Edges
20850-423	Anodized	Conductive	No
20850-425	Anodized	Conductive	No
20850-426	Anodized	Conductive	No
20850-424	Anodized	Conductive	No

## DIAGRAMS

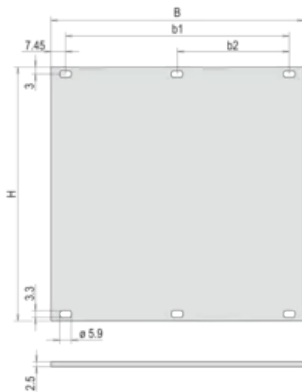

## AVERTIZARE

Produsele nVent trebuie instalate și utilizate numai așa cum este indicat în fișele de instrucțiuni și materialele de formare ale nVent. Fișele de instrucțiuni sunt disponibile pe [www.nvent.com](http://www.nvent.com) și de la reprezentantul dvs. de servicii clienți nVent. O instalare incorectă, o utilizare abuzivă, o aplicare greșită sau orice altă lipsă de respectare completă a instrucțiunilor și avertismentelor nVent poate duce la defectarea produsului, la deteriorarea proprietății, la răniri corporale grave și moarte și/sau poate anula garanția dvs.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Portofoliul nostru puternic de mărci:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**