

Front Panel, Front Shielded, Side Hinged

Front panel with textile EMC gasket, side hinged assembly.



CERTIFICATIONS



CARACTERISTICI

Front panel with textile EMC gasket

Enables mounting onto the horizontal rails

Suitable for subracks and cases


Hinges can be fitted on left or right

SPECIFICAȚII

Depth (D):	2.5mm
Rack Width:	84HP
Material:	Aluminiu
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel without Handle
EMC Shielding:	No (Retrofittable)

Table 1/2						
Număr de catalog	Rack Height	Package Quantity	Mounting	Gasket Type	Front Finish	Rear Finish
20848-611	3U	1	Hinged, Side	Textile EMC	Anodized	Conductive
20848-617	6U	1	Hinged, Side	Textile EMC	Anodized	Conductive

Table 2/2			
Număr de catalog	Treated Edges	Height (H)	Width (W)
20848-611	No	128.4mm	426.4mm
20848-617	No	261.8mm	426.4mm

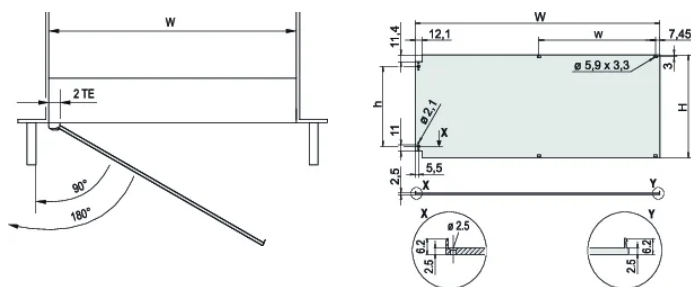

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Straubenhardt, Germany
 +49.7082.794.0
 Betschdorf, France
 +33.3.88.90.64.90
 Warsaw, Poland
 +48.22.209.98.35
 Assago, Italy
 +39.02.932.7141
 Chat with us:
nvent.com/schroff

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE