
 




# Commercial MI Wiring

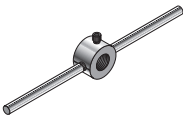
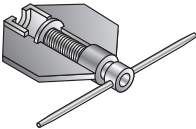
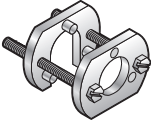
CONNECT AND PROTECT

## Tools

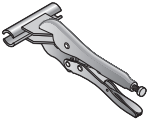
 

 
### CABLE STRIPPING TOOLS

Product name	Order reference	Description
<b>Power Stripper Tool</b> 	PSTKIT	Power Stripper Tool kit, containing adapter head, 23 bushings, 2 blades and 2 Allen Keys.
	<b>Replacement parts for Power Stripper Tool:</b>	
	PWBL	Bushings for 0.466" to 0.543" diameter cables
	PWBM	Bushings for 0.372" to 0.465" diameter cables
	PWBS	Bushings for 0.281" to 0.371" diameter cables
	PWBXS	Bushings for 0.198" to 0.280" diameter cables
	PWBTS	Bushings for shielded twisted cables
PWBLADE	Replacement blade for Power Stripper Tool and Ratchet Stripper Tool.	
<b>Sheathmaster</b> 	GL	Hand-type stripping tool to strip the sheath of copper-sheathed Mineral Insulated (MI) cable. For use with MI cable sizes up to and including 250 kcmil.
	GLB	Replacement blade for Sheathmaster GL tool.
<b>Ratchet Type Stripping Tool</b> 	RSTRIPKIT	Ratchet Type Stripping Tool kit for stripping the sheath of copper-sheathed MI cables with diameters of 0.684 inches and greater. The Ratchet Type Stripping Tool head must be inserted into a conduit threading tool such as the RIDGID® Model 00-R (included) or RIDGID® Model 770 power driver tool with 00-R adapter or equivalent (not included).  A cable guide bushing (not included) is required for each cable diameter to be stripped (see below).
	PSTRIPB	Replacement blade for Ratchet Type Stripping Tool.
<b>Cable Guide Bushing</b> 	<b>Cable guide bushings for use with Ratchet Stripper only:</b>	
	PSBUSH1000	Bushings for 1" diameter cables
	PSBUSH975	Bushings for 0.975" diameter cables
	PSBUSH865	Bushings for 0.865" diameter cables
	PSBUSH834	Bushings for 0.834" diameter cables
	PSBUSH768	Bushings for 0.768" diameter cables
	PSBUSH746	Bushings for 0.746" diameter cables
	PSBUSH730	Bushings for 0.730" diameter cables
	PSBUSH710	Bushings for 0.710" diameter cables
PSBUSH684	Bushings for 0.684" diameter cables	

 
 
## PYROPOTTER, CRIMPING AND COMPRESSION TOOLS

Product name	Order reference	Description
<b>Pyropotter Pot Threading Tool</b> 		The Pyropotter Tool is used to thread brass pots onto copper-sheathed MI cables.
	PYROPOT12	Tool to install 1/2 in pot
	PYROPOT34	Tool to install 3/4 in pot
	PYROPOT1	Tool to install 1 in pot
	PYROPOT114	Tool to install 1-1/4 in pot
<b>Handle Type Crimping And Compression Tool</b> 		Heavy duty handle type crimping and compression tool easily completes the MI cable termination. For use with termination kits using fiber caps and mastic compound seal.
	MIC1/2	1/2" crimping and compression tool
	MIC3/4	3/4" crimping and compression tool
<b>Screw Type Crimping and Compression Tool</b> 		Screw type crimping and compression tool easily completes the MI cable termination. For use with termination and splice kits using fiber caps and mastic compound seal.
	CC1/2	1/2" crimping and compression tool
	CC3/4	3/4" crimping and compression tool
	CC1	1" crimping and compression tool
	CC11/4	1-1/4" crimping and compression tool for cable diameters from 0.699" to 0.84"
CC11/4M	1-1/4" crimping and compression tool for cable diameters from 0.84" to 1.00"	


## CABLE HANDLING TOOLS

Product name	Order reference	Description
<b>Handvise</b> 	HANDVISE	Vise-grip-type tool used to support cable while installing termination.
<b>Bending Hickey</b> 		Bending tool assists in making bends in MI cable.
	HICMED	Medium size 0.39" – 0.63" OD cable
	HICLGE	Large size 0.63" – 0.75" OD cable
<b>Pyrohickey</b> 	PYROHICKEY381	Heavy duty bending tool specially modified to prevent damage to the MI cable sheath when making bends in the cable. Fits a standard conduit bending tool handle with 1" threads (handle not supplied).  Bends 3/8" to 1" MI cable.
<b>Cable Straightener</b> 	STRSM	Manual tool to straighten MI cables up to 1/2" in diameter.

## BANDING TOOLS

Product name	Order reference	Description
<b>Tensioner</b> 	T34P	Ratchet type tensioning tool tightens stainless steel banding used to support MI cables.
<b>Crimper</b> 	S12P	Crimping tool used to crimp clip onto stainless steel banding.

## TWISTED PAIR DRAIN WIRE TOOL

Product name	Order reference	Description
<b>Twisted Pair Drain Wire Tool</b> 	TWISTPRTOOL	Drain wire tool used to fix drain wire ring to shield of shielded twisted pair copper-sheathed MI cable.

### North America

Tel +1.800.545.6258  
 Fax +1.800.527.5703  
[thermal.info@nVent.com](mailto:thermal.info@nVent.com)

### Europe, Middle East, Africa

Tel +32.16.213.511  
 Fax +32.16.213.603  
[thermal.info@nVent.com](mailto:thermal.info@nVent.com)

### Asia Pacific

Tel +86.21.2412.1688  
 Fax +86.21.5426.3167  
[cn.thermal.info@nVent.com](mailto:cn.thermal.info@nVent.com)

### Latin America

Tel +1.713.868.4800  
 Fax +1.713.868.2333  
[thermal.info@nVent.com](mailto:thermal.info@nVent.com)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**