 
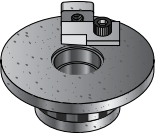


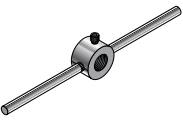


Tools

 
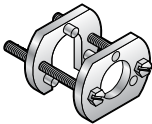
CABLE STRIPPING TOOLS

Product name	Order reference	Description
 Sheathmaster GL Tool	GL	Hand-type stripping tool to strip the sheath of copper-sheathed Mineral Insulated (MI) cable. For use with MI cable sizes up to and including 250 kcmil.
	GLB	Replacement blade for Sheathmaster GL Tool.
 Ratchet Type Stripping Tool	RSTRIPASY	Ratchet sheath stripper head for stripping the sheath of copper-sheathed MI cables with diameters of 0.684 inches and greater. The Ratchet Type Stripping Tool head must be inserted into a conduit threading tool (not supplied) such as RIDGID® Model 00-R (included), or RIDGID® Model 770 power drive tool with 00-R adapter or equivalent (not included). A cable guide bushing (not included) is required for each cable diameter to be stripped (see below).
	PSTRIPB	Replacement blade for Ratchet Type Stripping Tool.
 Cable Guide Bushing	PSBUSH1000	Bushings for 1" diameter cables
	PSBUSH975	Bushings for 0.975" diameter cables
	PSBUSH865	Bushings for 0.865" diameter cables
	PSBUSH834	Bushings for 0.834" diameter cables
	PSBUSH768	Bushings for 0.768" diameter cables
	PSBUSH746	Bushings for 0.746" diameter cables
	PSBUSH730	Bushings for 0.730" diameter cables
	PSBUSH710	Bushings for 0.710" diameter cables
	PSBUSH684	Bushings for 0.684" diameter cables
 T-bar	12TEE12	12" T-bar stripper with 4" handle
	24TEE12	24" T-bar stripper with 6" handle Used to strip the sheath of heavy copper or stainless steel sheath MI cables.

 
 

 
PYROPOTTER, CRIMPING AND COMPRESSION TOOLS

Product name	Order reference	Description
 Pyropotter Pot Threading Tool		The Pyropotter Tool is used to thread brass pots onto copper-sheathed MI cables.
	PYROPOT12	Tool to install 1/2 in pot
	PYROPOT34	Tool to install 3/4 in pot
	PYROPOT1	Tool to install 1 in pot
	PYROPOT114	Tool to install 1-1/4 in pot


PYROPOTTER, CRIMPING AND COMPRESSION TOOLS

Product name	Order reference	Description
Handle Type Crimping and Compression Tool 		Heavy duty handle type crimping and compression tool easily completes the MI cable termination. For use with termination kits using fiber caps and mastic compound seal.
	MIC1/2	1/2" crimping and compression tool
	MIC3/4	3/4" crimping and compression tool
Screw Type Crimping and Compression Tool 		Screw type crimping and compression tool easily completes the MI cable termination. For use with termination kits using fiber caps and mastic compound seal.
	CC1	1" crimping and compression tool
	CC11/4	1-1/4" crimping and compression tool for cable diameters from 0.699" to 0.84"
	CC11/4M	1-1/4" crimping and compression tool for cable diameters from 0.84" to 1.00"

CABLE HANDLING TOOLS

Product name	Order reference	Description
Handvise 	HANDVISE	Vise-grip-type tool used to support cable while installing termination.
Bending Hickey 	HICMED	Medium size 0.39" – 0.63" OD cable
	HICLGE	Large size 0.63" – 0.75" OD cable
	HIC114	Extra large size 0.75" – 1.25" OD cable
Pyrohickey 		Heavy duty bending tool specially modified to prevent damage to the MI cable sheath when making bends in the cable. Fits a standard conduit bending tool handle with 1" threads (handle not supplied).
	PYROHICKEY381	Bends 3/8" to 1" MI cable.
Cable Straightener 	STRSM	Manual tool to straighten MI cables up to 1/2" in diameter.

TWISTED PAIR DRAIN WIRE TOOL

Product name	Order reference	Description
Twisted Pair Drain Wire Tool 	TWISTPRTOOL	Drain wire tool used to fix drain wire ring to shield of shielded twisted pair copper-sheathed MI cable.

North America

Tel +1.800.545.6258
Fax +1.800.527.5703
thermal.info@nVent.com

Europe, Middle East, Africa

Tel +32.16.213.511
Fax +32.16.213.604
thermal.info@nVent.com

Asia Pacific

Tel +86.21.2412.1688
Fax +86.21.5426.3167
cn.thermal.info@nVent.com

Latin America

Tel +1.713.868.4800
Fax +1.713.868.2333
thermal.info@nVent.com



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER