

FleXbus IP55 Conductor Entry, Single Entry, 126 mm x 102 mm x 175 mm

Data Solutions

KATALOGNUMMER

FLEXCEIP55C501



nVent ERIFLEX FleXbus IP55 Conductor Entries can be used for switchboard and/or power supply cover to upgrade an installation to IP55 level. Protect the nVent ERIFLEX FleXbus Conductor insulation against sharp edges from power supply or switchboard top cover.

CERTIFIERINGAR



DESIGN

Uppfyller RoHS

Made with soft PVC to follow any potential conductor bending radius

Sealing around the conductor is made by a self-fusing tape with a strong adhesive

Good resistance to solvent and hydrocarbon splashes

Adaptable to any nVent ERIFLEX FleXbus conductor cross section by cutting the top material with traditional cutter

High acid resistance

UV resistance

Flame retardant

PRODUKTATTRIBUT

Artikelnummer: 508140

Material: Polyvinylklorid

Kapslingsklass: IP55

Typ: Enskild genomföring

Arbetstemperatur: -40 to 140°C

A.: 126mm

B.: 102mm


C.: 175mm

Ledarstorlek: 220 mm²; 360 mm²; 545 mm²; 640 mm²

Vridmoment (TQ): 2.5N·m

Enhetsvikt: 0.6kg

DIAGRAMS

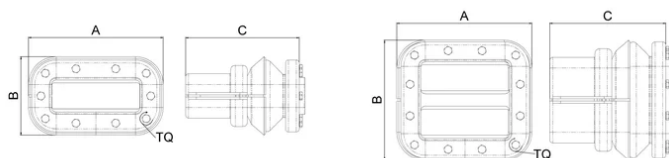

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE