

ATCA Front Panel Kit With Spring Loading



AdvancedTCA

前面板，适用于带压铸尾端件的铝型材或不锈钢材质弹簧支撑IEA把手（柱塞式或杆式）。

认证



功能

前面板（使用压铸端件加固）

ATCA IEA 把手，带弹簧承载装置

EMC 织物垫片和固定材料

技术参数

机架宽度： 6HP

机架高度： 8U

附件类型： 前面板

产品类型： 前面板


Table 1/2

物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-160	不锈钢		1	未加工	未加工	1mm
20818-169	铝	钝化	1	未加工	未加工	1mm

物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-161	不锈钢		1	未加工	未加工	1mm
20818-170	铝	钝化	1	未加工	未加工	1mm

Table 2/2		
物料号	高度 (H)	宽度 (W)
20818-160	323.15mm	28.95mm
20818-169	323.15mm	28.95mm
20818-161	323.15mm	28.95mm
20818-170	323.15mm	28.95mm

图

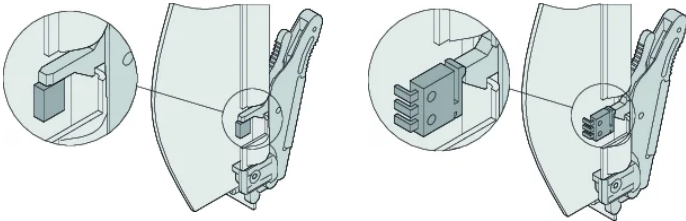

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE